


- 1 Type**
- SC** With key (Keyed alike)
 - SU** With key (Keyed differently)
 - SCK** With wing knob (Keyed alike)
 - SUK** With wing knob (Keyed differently)
 - SCT** With T-handle (Keyed alike)
 - SUT** With T-handle (Keyed differently)
 - LCG** With lever (Keyed alike) (only in SW)
 - LUG** With lever (Keyed differently) (only in SW)

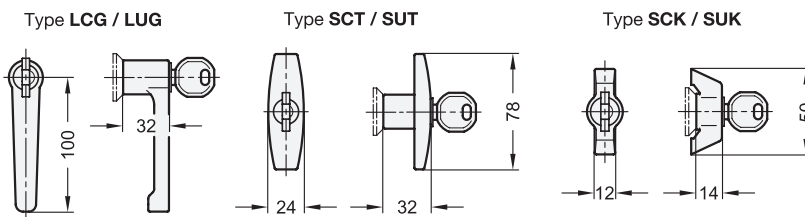

Metric table



Dimensions in: millimeters - inches

Latch distance A											d	h		
											Type SC, SU	Type SCK, SUK, SCT, SUT, LCG, LUG	Type SC, SU	Type SCK, SUK, SCT, SUT, LCG, LUG
4	8	13	16	20	24	28	32	36	40	45	28	32	4	6
0.16	0.31	0.51	0.63	0.79	0.94	1.10	1.26	1.42	1.57	1.77	1.10	1.26	0.16	0.24
6	10	14	18	22	26	30	34	38	42	50	28	32	4	6
0.24	0.39	0.55	0.71	0.87	1.02	1.18	1.34	1.50	1.65	1.97	1.10	1.26	0.16	0.24

Specification



- Cam lock housing
Zinc die-cast
- Housing collar
 - Chrome plated finish —
 - Powder coated
 - Black, RAL 9005, textured finish ● SW
- Latch arm / assembly hardware
Steel, zinc plated, blue passivated finish
- Key
Nickel silver with plastic hand piece
- Wing knob / T-handle
Plastic
Technopolymer (Polyamide PA)
Black, matte finish
- Lever body
Zinc die-cast
Powder coated
Black, RAL 9005, textured finish
- Plastic Characteristics → page 2135
- RoHS compliant

Information

GN 115 cam locks close via a turning operation limited to 90° (quarter of a turn), which moves the latch arm behind the door frame. The beveled edges of the latch arm create a smooth latching of the door.

The 22 different off-set latch arm options allow for “Latch distance A” to be set between 4 mm and 50 mm.

Keyed differently cam locks are available in more than 200 variations, whose keys are marked with numbers.

Two keys are supplied with each cam lock. The key may be inserted or withdrawn in both the locked and unlocked positions.

Product comes supplied with a loosely enclosed latch arm.

see also...

- Construction and Assembly Instructions → page 1261
- List of Cam Latch / Cam Lock Types → page 1256
- Cam Latches GN 115 (Zinc Die-Cast, with Operating Elements) → page 1260
- Cam Locks GN 115 (Stainless Steel) → page 1268

How to order (Chrome plated housing collar)	1 Type
GN 115-SC-42	2 Latch distance A

How to order (Powder coated housing collar)	1 Type
GN 115-SU-18-SW	2 Latch distance A
	3 Finish (Housing collar)

3.1
3.2
3.3
3.4
3.5
3.6
3.7
3.8
3.9
3.10