


Application examples

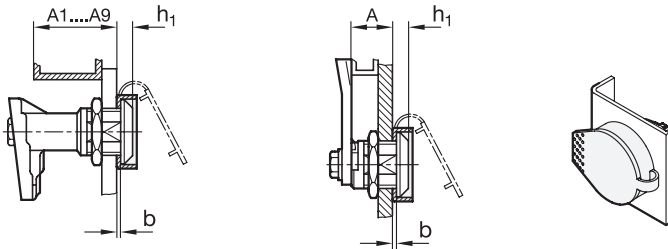

GN 119 cam door latches

GN 115 cam latches

1) The clamping range / latch distance .A1 - A9 is reduced by the dimension "b".

Metric table

Dimensions in: millimeters - inches

¹ d	² s	b	h ₁	h ₂	Length l	For series
29 1.14	14.5 0.57	2 0.08	6 0.24	11 0.43	18.5 0.73	GN 115.1 / GN 115.6
36 1.42	20.5 0.81	2 0.08	8 0.31	12 0.47	23 0.91	GN 115 / GN 115.8 / GN 119 / GN 516 / GN 516.1 / GN 516.5

Specification

- Plastic
Technopolymer (Polyethylene)
Black

- RoHS compliant

Information

GN 120 protective caps are used in combination with key-actuated latching / locking devices. They prevent dirt from entering the key mechanism and the latching device and can be mounted as required in a 90° grid pattern together with the housing of the latching device.

GN 120 protective caps are suitable for the following cam latches / cam locks:

- GN 115.1 / GN 115.6 mini cam latches / cam locks
- GN 115 cam latches / cam locks
- GN 115.8 cam latches / cam locks with hook
- GN 119 cam door latches
- GN 516 compression cam latches
- GN 516.1 compression cam latches
- GN 516.5 compression cam latches

<p>How to order</p> <p>¹ ²</p> <p>GN 120-36-20.5</p>	1 Diameter d
	2 Square s