

# GN 128.2


Aluminum / Stainless Steel

# Lift-Off Hinges


Weldable



**JW WINCO**  
A Ganter Company

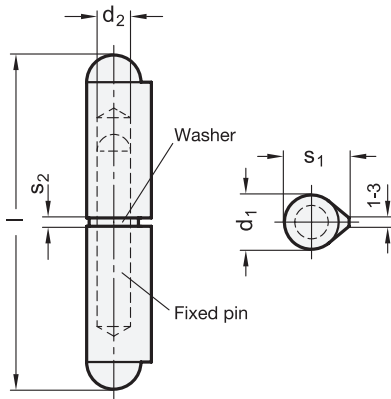

Installation example

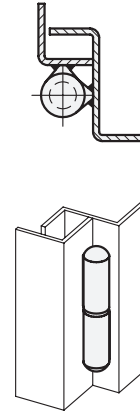

SS Stainless Steel

## Metric table



Dimensions in: millimeters - inches

Length I Material NI Material AL	Material A4	d <sub>1</sub>	d <sub>2</sub> Pin	s <sub>1</sub>	s <sub>2</sub>
60 2.36	-	10 0.39	6 0.24	12 0.47	2 0.08
80 3.15	80 3.15	13 0.51	8 0.31	15.5 0.61	2 0.08
100 3.94	100 3.94	16 0.63	10 0.39	20 0.79	3 0.12
120 4.72	120 4.72	16 0.63	11 0.43	20 0.79	3 0.12
150 5.91	-	20 0.79	13 0.51	25.5 1.00	3 0.12
180 7.09	-	20 0.79	14 0.55	25.5 1.00	3 0.12

## Specification



- Stainless steel **NI**
  - Body  
Stainless steel AISI 304
  - Pin and washer  
Stainless steel AISI 303
- Stainless steel **A4**
  - Body  
Stainless steel AISI 316
  - Pin and washer  
Stainless steel AISI 316
- Aluminum **AL**
  - Body  
Weldable, 3.3206
  - Pin and washer  
Stainless steel AISI 303

• RoHS compliant

## Information

GN 128.2 lift-off hinges are produced from drawn weldable profiled stainless steel or aluminum extrusions.

The hinge pin is retained in the lower half of the hinge.

see also...

- List of Hinge Types

### How to order

**GN 128.2-80-A4**

- 1 Length I
- 2 Material

3.1

3.2

3.3

3.4

3.5

3.6

3.7

3.8

3.9

3.10

