


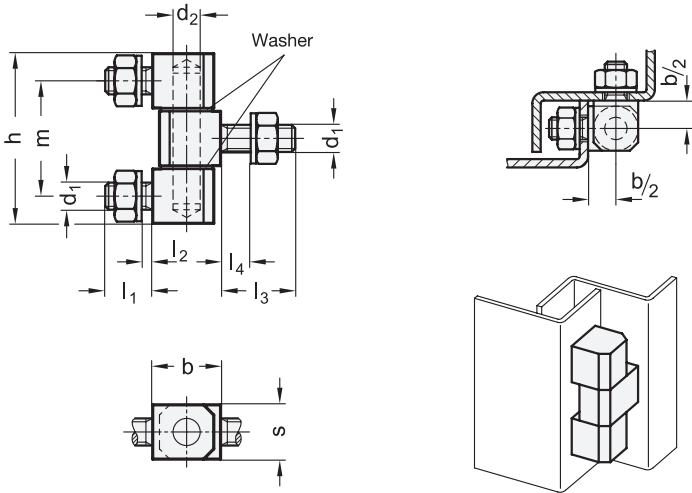

Metric



SS

Stainless Steel

2

Type

D Consisting of three parts

Metric table

1

s	b	d ₁	d ₂ Pin	h	l ₁	l ₂	l ₃	l ₄ max.	m
12	15	M 6	6	39.2	10	5	14	9	27.2
0.47	0.59		0.24	1.54	0.39	0.20	0.55	0.35	1.07
16	20	M 8	8	49	14	8	22	16	33
0.63	0.79		0.31	1.93	0.55	0.31	0.87	0.63	1.30

Dimensions in: millimeters - inches

3

Specification

- Body, pin, washer
 - Stainless steel AISI 303
 - Stainless steel AISI 316
- Hex nut ISO 4032
 - Stainless steel AISI 304
- Serrated washer DIN 6797
 - Stainless steel AISI 304
- Stainless Steel Characteristics → page QVX
- RoHS compliant

NI

A4

Information

GN 129.5 hinges are used for doors which are flush with the frame on the outside.

They are especially suitable for tamper-proof doors and flaps. When mounted inside, the hinges are not removable from the outside and therefore protect against manipulation.

see also...

- List of Hinge Types → page QVX
- Hinges GN 129.2 → page QVX

How to order	1 Square s
1 2 3 GN 129.5-16-D-A4	2 Type
	3 Material