


Application example

Mounting of a handwheel with keyway on a shaft

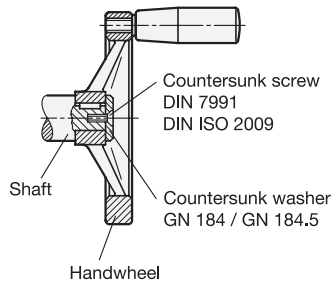

SS Stainless Steel

Metric table



Dimensions in: millimeters - inches

d ₁	d ₂	d ₃	s	For DIN 7991 / DIN ISO 2009 countersunk screws with thread size
16 .63	4.3 .17	8 .31	3 .12	M 4
20 .79	4.3 .17	8 .31	3 .12	M 4
22 .87	5.3 .21	10 .39	3.5 .14	M 5
25 .98	5.3 .21	10 .39	3.5 .14	M 5
28 1.10	5.3 .21	10 .39	3.5 .14	M 5
32 1.26	6.4 .25	12 .47	4 .16	M 6
36 1.42	6.4 .25	12 .47	4 .16	M 6
40 1.57	6.4 .25	12 .47	5 .20	M 6
45 1.77	6.4 .25	12 .47	6 .24	M 6
52 2.05	6.4 .25	12 .47	6 .24	M 6

Specification

- **GN 184**
Steel
- Turned
- Blackened finish
- **GN 184.5**
Stainless steel
European standard No. 1.4305 (AISI 303)
- Turned
- Matte shot-blasted finish
- **RoHS compliant**

Information

GN 184 and GN 184.5 countersunk washers are retained to the face of the shaft end with DIN 7991 / DIN ISO 2009 countersunk head screws, forming a clean-look end cap.

A typical application example would be the retention of a handwheel with keyway to a shaft.

How to order (Steel)	1	Outer diameter d ₁
GN 184-28		

How to order (Stainless steel)	1	Outer diameter d ₁
GN 184.5-36		