


Application example

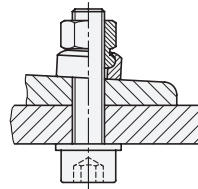

Metric



Metric table

Dimensions in: millimeters - inches

| ¹ d ₁ | ² d ₂ Thread | Length l ≈ | A/F |
|-----------------------------|------------------------------------|--------------|------------|
| 17 .67 | M 8 | 14 .55 | 13 .51 |
| 21 .83 | M 10 | 17.5 .69 | 16 .63 |
| 24 .94 | M 12 | 21.5 .85 | 18 .71 |
| 30 1.18 | M 16 | 28 1.10 | 24 .94 |
| 36 1.42 | M 20 | 35 1.38 | 30 1.18 |
| 44 1.73 | M 24 | 42.5 1.67 | 36 1.42 |

Specification

- Steel
 - Property class 10
 - Blackened finish
- RoHS compliant

Information

GN 347 swivel hexagon nuts are capable of clamping slanting surfaces up to 3° without disturbing or twisting the clamped surface.

How to order

¹ ²
GN 347-30-M16

1 Diameter d₁

2 Thread d₂