


Application example

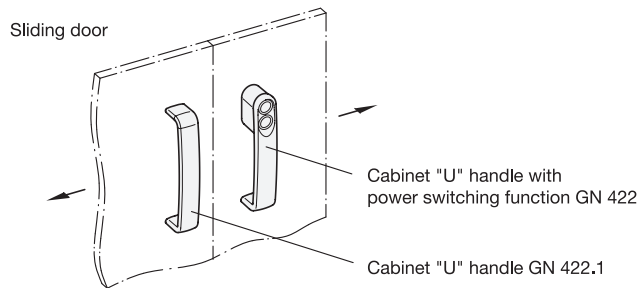

Metric table

Dimensions in: millimeters - inches

² $l_1 \pm 0.2$	a	b	d Thread	h	l_2	t
117 4.61	11 0.43	33 1.30	M 6	44 1.73	128 5.04	12 0.47
148 5.83	11 0.43	33 1.30	M 6	44 1.73	159 6.26	12 0.47
172 6.77	11 0.43	33 1.30	M 6	44 1.73	183 7.20	12 0.47

Specification

- Aluminum die-cast **AL**
- Powder coated
- Black, RAL 9005, textured finish **● SW**
- Silver, RAL 9006, textured finish **● SR**
- Load Rating Information → page 2068
- RoHS compliant

Information

GN 422.1 aluminum die-cast cabinet "U" handles fit perfectly into a wide range of applications thanks to their timeless design.

They are also designed as a complementary handle for GN 422 cabinet "U" handles with power switching function.

see also...

- Cabinet "U" Handles GN 422 (with Power Switching Function) → page 124

How to order	1 Material
GN 422.1-AL-117-SR	2 Length l_1
	3 Finish

1.1
1.2
1.3
1.4
2.1
2.2
2.3
2.4