


Bores for countersunk screws
DIN 7991

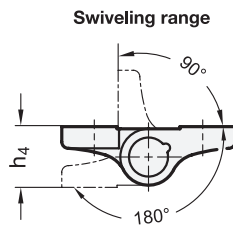

Metric

4 Type

A 2x2 bores for countersunk screws

Metric table

Dimensions in: millimeters - inches

² l ₁	³ l ₂	d	h ₁	h ₂	h ₃	h ₄	l ₃	m ₁	m ₂
60	60	8.3	18.5	7.5	9.5	19	20	36	36
2.36	2.36	0.33	0.73	0.30	0.37	0.75	0.79	1.42	1.42

Specification

- Body
Zinc die-cast **ZD**
Powder coated
Black, RAL 9005, textured finish **●SW**
Silver, RAL 9006, textured finish **●SR**
- Cover cap
Plastic
Technopolymer (Polyacetal POM)
Temperature resistant up to 176 °F (80 °C)
- RoHS compliant

Information

GN 437.1 hinges fit perfectly into a wide range of application thanks to their timeless design. They are also matched with the GN 437 functional hinge family as complementary hinges.

see also...

- List of Hinge Types
- Hinges GN 437 (with Adjustable Friction)
- Hinges GN 437.2 (with Clamp)
- Hinges GN 437.3 (with Spring-Loaded Return)
- Hinges GN 437.4 (with Detent)

Accessory

- Spacer plates GN 2370
- Spacer plates with tapped holes GN 2372

How to order

GN 437.1-ZD-60-60-A-SR

¹	Material
²	Width l ₁
³	Length l ₂
⁴	Type
⁵	Color

3.1
3.2
3.3
3.4
3.5
3.6
3.7
3.8
3.9
3.10

