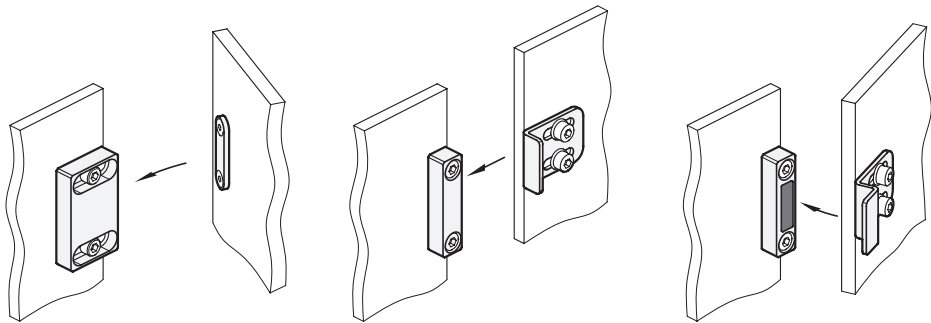
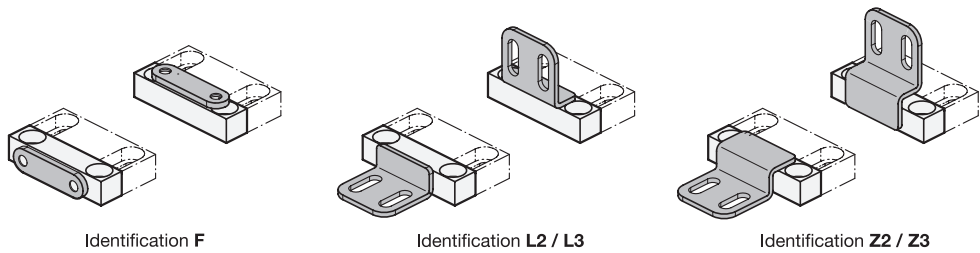


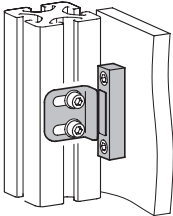
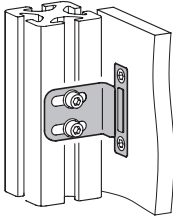
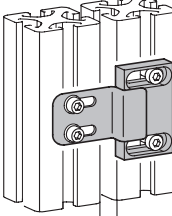
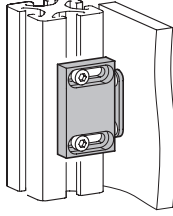
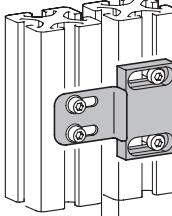
Application examples



Possible combinations magnetic catch - strike plate



Use on profile systems

Dimensions in: millimeters - inches					
Profile system grid dimension	Magnetic catch with strike plate Type - Identification A1 - L ...		A2 - Z ...	C2 - F	C2 - L ...
	Surface-mounted door	Surface-mounted door - Countersunk magnet	Inset door	Surface-mounted door	Sliding door
					
20 0.79	-	L2	Z2 s = 0 - 10 mm (0 - 0.39")	F	L2 s = 0 - 10 mm (0 - 0.39")
30 1.18	-	L2	Z3 s = 0 - 15 mm (0 - 0.59")	F	L3 s = 0 - 15 mm (0 - 0.59")
40 1.57	L2	L3	Z3 s = 0 - 10 mm (0 - 0.39")	F	L3 s = 0 - 10 mm (0 - 0.39")
45 1.77	L2	L3	Z3 s = 0 - 7 mm (0 - 0.28")	F	L3 s = 0 - 7 mm (0 - 0.28")