


Application example

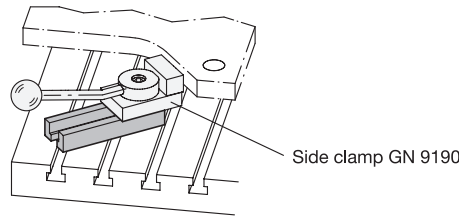

Metric table

Dimensions in: millimeters - inches

1 b ₁	2 l ₁	3 d Thread	b ₂	b ₃	h ₁	h ₂	l ₂	l ₃	For side clamp slot width a		
									GN 9190	GN 9190.1	GN 9190.2
30 1.18	100 3.94	M 8	15 0.59	9 0.35	15 0.59	6.5 0.26	63 2.48	20 0.79	10 0.39	10 0.39	10 0.39
40 1.57	120 4.72	M 12	20 0.79	13 0.51	20 0.79	7.5 0.30	72 2.83	25 0.98	12 0.47	14 0.55	14 0.55
60 2.36	140 5.51	M 16	26 1.02	17 0.67	30 1.18	13 0.51	80 3.15	30 1.18	-	18 0.71	18 0.71

Specification

- Steel
 - Tempered
 - Blackened finish
- RoHS compliant

Information

Slotted support blocks GN 9190.3 are provided as an accessory for side clamps GN 9190 / GN 9190.1 / GN 9190.2.

They can also be used to fasten side clamps across the T-slot in any position.

see also...

- Side Clamps GN 9190 (with Eccentric Cam Lever) → page QVX
- Side Clamps GN 9190.1 (with Clamping Thread) → page QVX
- Side Clamps GN 9190.2 (with Support Plate) → page QVX

How to order

GN 9190.3-30-100-M8

1	Width b ₁
2	Length l ₁
3	Thread d