


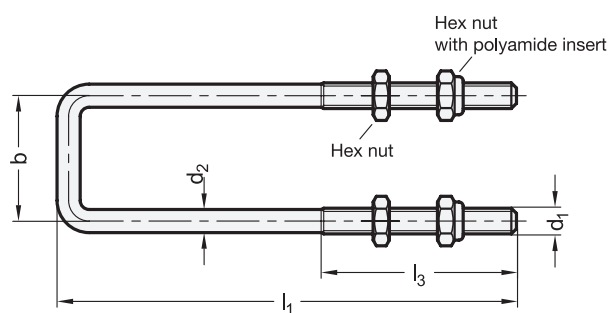

Metric table

1

2

3

</

* Standard version when selecting type "with square U-bolt" on the respective standard sheet.

Specification

Square U-bolt

- Steel, zinc plated, blue passivated finish
- Stainless steel AISI 304

Hex nuts with polyamide insert

DIN 982 for M4 | DIN 985 for M6 / M8

- Steel, zinc plated for ST
- Stainless steel A2 for NI

Hex nuts

DIN 934 for M4 | DIN 936 for M6 / M8

- Steel, zinc plated for ST
- Stainless steel A2 for NI

RoHS

On request

- Stainless steel AISI 316

ST
NI
A4

Square U-bolts GN 951.1 are used when latch type toggle clamps require a greater distance to the latch bracket. The latch type toggle clamps are also available without square U-bolt.

see also...

	Page
GN 851 Horizontal Latch Type Toggle Clamps	QVX
GN 851.1 Vertical Latch Type Toggle Clamps	QVX
GN 851.2 Horizontal Latch Type Toggle Clamps	QVX
GN 851.3 Horizontal Latch Type Toggle Clamps	QVX
GN 851.4 Vertical Latch Type Toggle Clamps	QVX

Technical Information

Stainless Steel Characteristics

QVX

How to order

1

2

3

4

GN 951.1-M6-32-130-NI

1	Thread d ₁
2	Width b
3	Length l ₁
4	Material

www.jwwinco.com | 1-800-877-8351

 **WARNING:** Cancer and Reproductive Harm — www.P65Warnings.ca.gov

1