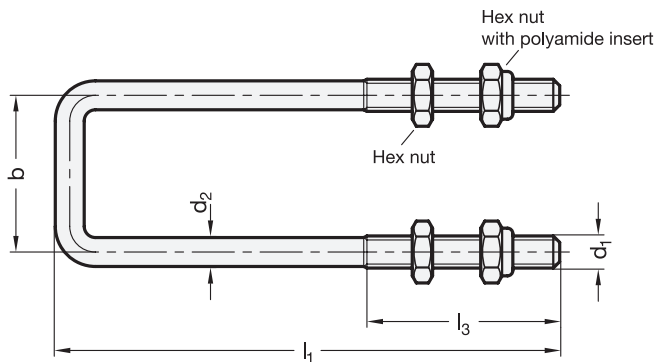


Metric table

1

2

3


d₁

b

l₁


d₂

l₃

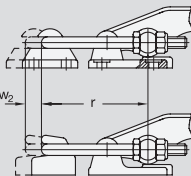

GN 852 / GN 852.3

Size	r at w ₂ = 0	w ₂
M 10	96	15 0.59
M 10	146	15 0.59
M 10	176	15 0.59
M 10	226	15 0.59
M 12	107	25 0.98
M 12	156	36 1.42
M 12	306	36 1.42
M 12	366	36 1.42

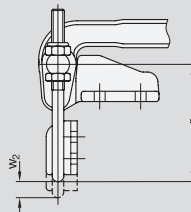

GN 852.1

Size	r at w ₂ = 0	w ₂
1400	95 3.74	15 0.59
1400*	145 5.71	15 0.59
1400	175 6.89	15 0.59
1400	225 8.86	15 0.59
-	-	-
-	-	-
-	-	-
-	-	-

Dimensions in: millimeters / inches

* Standard version when selecting type “with square U-bolt” on the respective standard sheet.

Specification

Square U-bolt

- Steel, zinc plated, blue passivated finish
- Stainless steel AISI 304

ST
NI

Hex nuts with polyamide insert

DIN 985

- Steel, zinc plated for ST
- Stainless steel A2 for NI

Hex nuts

DIN 936

- Steel, zinc plated for ST
- Stainless steel A2 for NI

Square U-bolts GN 951.2 are used when latch type toggle clamps require a greater distance to the latch bracket. The latch type toggle clamps are also available without square U-bolt.

see also...

GN 852 Latch Type Toggle Clamps

GN 852.1 Latch Type Toggle Clamps

GN 852.3 Latch Type Toggle Clamps

Page

QVX

QVX

QVX

Technical Information

Stainless Steel Characteristics

QVX

RoHS

How to order

1

2

3

4

GN 951.2-M10-46-179-NI

1

Thread d₁

2

Width b

3

Length l₁

4

Material

www.jwwinco.com | 1-800-877-8351

 WARNING: Cancer and Reproductive Harm — www.P65Warnings.ca.gov

1