


Inch

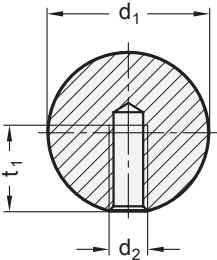

Inch table

2

3

Dimensions in: inches / millimeters

d ₁	d ₂									t ₁
0.75 19.1	10 x 32	10 x 24	-	-	-	-	-	-	-	0.38 9.7
1.00 25.4	10 x 32	10 x 24	-	-	-	-	-	-	-	0.38 9.7
1.00 25.4	1/4 x 20	1/4 x 28	5/16 x 18	5/16 x 24	3/8 x 16	-	-	-	-	0.50 12.7
1.38 35.1	1/4 x 20	1/4 x 28	5/16 x 18	3/8 x 16	3/8 x 24	5/16 x 24	7/16 x 20	1/2 x 13	1/2 x 20	0.63 16
1.88 47.8	3/8 x 16	3/8 x 24	5/8 x 11	1/2 x 13	1/2 x 20	5/8 x 18	-	-	-	0.75 19.1

Specification	1
Steel	ST
Highly polished	
Brass	MS
• Highly polished	
• Corrosion resistant in water	

Ball knobs BK are highly polished and turned from a solid bar stock. They are used on fixtures, machine tools, jigs and assemblies.

see also...	Page
DIN 319 Ball Knobs (Metric, Stainless Steel)	QVX
DIN 319 Ball Knobs (Metric, Steel and Aluminum)	QVX

How to order

1

2

3

BK-MS-1.00-5/16X18

1	Material
2	Handle diameter d ₁
3	Thread d ₂

