


Metric

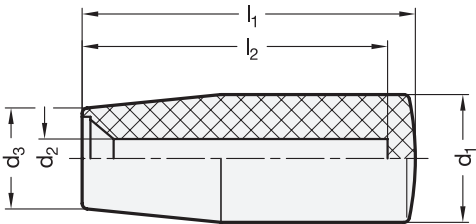

Metric table

1 2		Dimensions in: millimeters / inches							
d ₁	d ₂							d ₃	l₁ l₂
23 0.91	B 7	B 8	B 9	B 10	B 12	B 14		18 0.71	60 2.36 55 2.17

Specification

- Plastic, PVC
- Operating temperature up to 158 °F (70 °C)
 - Black
 - Molded blind bore
 - Push-fit mounting

RoHS

Cylindrical handles MVP offer a comfortable and elastic grip.

see also...	Page
MVP-CON Tapered Handle	QVX

Technical Information	
Plastic Characteristics	QVX

How to order 1 2 MVP-23-B7	1	Handle diameter d ₁
	2	Bore diameter d ₂