


Inch

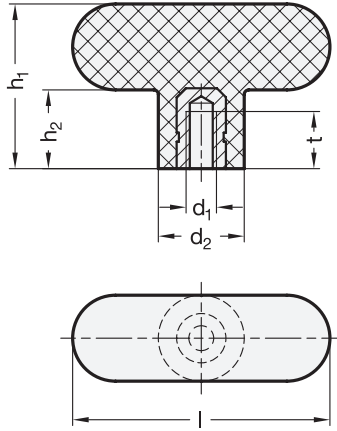

Inch table

Dimensions in: inches / millimeters

Length l	d ₁		d ₂	h ₁	h ₂	t	
2.25 57.2	1/4 x 20	5/16 x 18	3/8 x 16	0.75 19.1	1.44 36.6	0.69 17.5	0.50 12.7

Specification

Handle

- Nyoln plastic
- Operating temperature up to 200 °F (93 °C)
- Black, matte finish

Tapped insert

Brass

RoHS

On request

- Additional thread sizes
- Special stud assemblies (glued into place)

T-bar knobs TBK are a great choice for pull-action applications due to their ergonomically rounded shape.

Technical Information

Plastic Characteristics

Page

QVX

How to order

TBK-2.25-3/8X16

1 Handle length l

2 Thread d₁

1.1
1.2
1.3
1.4
2.1
2.2
2.3
2.4

