




Metric

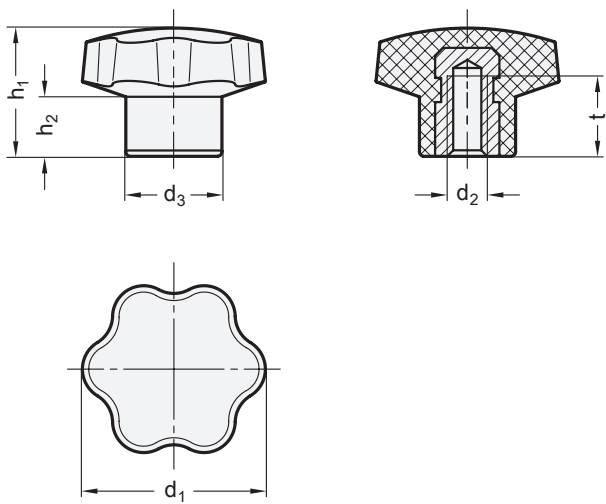

Metric table

1		2		Dimensions in: millimeters / inches			
d ₁		d ₂		d ₃	h ₁	h ₂	t
20 0.79		M 4	M 5	M 6	13 0.51	15 0.59	9 0.35
30 1.18		M 5	M 6	-	17 0.67	24 0.94	9 0.35
30 1.18		M 8	-	-	17 0.67	24 0.94	15 0.59
40 1.57		M 6	-	-	21 0.83	28 1.10	13 0.51
40 1.57		M 8	-	-	21 0.83	28 1.10	15 0.59
40 1.57		M 10	-	-	21 0.83	28 1.10	16 0.63
50 1.97		M 8	-	-	25 0.98	33 1.30	15 0.59
50 1.97		M 10	-	-	25 0.98	33 1.30	16 0.63
50 1.97		M 12	-	-	25 0.98	33 1.30	18 0.71

Specification

Six-lobed knob

- Plastic, phenolic (PF)
- Operating temperature up to 300 °F (150 °C)
 - Black, shiny finish

Tapped insert

Brass

RoHS

On request

- For certain minimum quantities, stainless steel inserts

The solid design of the six-lobed knobs VB is an excellent choice for food applications or any application where bacteria accumulation is unwanted.

see also...

	Page
VB-FP Six-Lobed Knobs (with Brass Tapped Through Insert)	QVX
VP Six-Lobed Knobs (with Steel Threaded Stud)	QVX

Technical Information

Plastic Characteristics	QVX
-------------------------	-----