


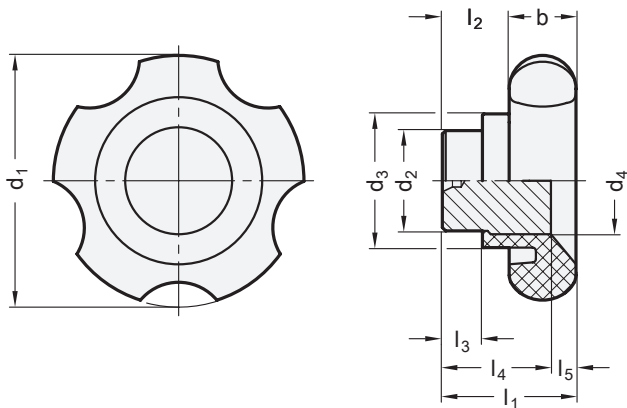

Universal table

Dimensions in: millimeters / inches										
d ₁	Bore	d ₂	d ₃	d ₄	b	l ₁	l ₂	l ₃	l ₄	l ₅
60 2.36	Blank	24 0.94	34 1.34	26 1.02	16 0.63	32 1.26	16 0.63	10 0.39	26 1.02	6 0.24
75 2.95	Blank	30 1.18	40 1.57	32 1.26	20 0.79	40 1.57	20 0.79	12 0.47	32.5 1.28	7.5 0.30
90 3.54	Blank	35 1.38	47 1.85	40 1.57	20 0.79	44 1.73	24 0.94	14 0.55	36.7 1.44	7.3 0.29

Specification

Body

- Plastic, Phenolic (PF)
- Operating temperature up to 266 °F (130 °C)
 - Black, shiny finish

Hub bushing

Steel, zinc plated

RoHS

On request

- Other modifications such as inch and metric through bores, blind bores, threads, etc.

Five-lobed control knobs VUA are ideally suited for light-medium duty adjusting or clamping applications.

see also...	Page
VUM Five-Lobed Control Knobs	QVX
VU Five-Lobed Control Knobs	QVX

Technical Information

Keyways WN 6885 / DIN 6885-1	QVX
Plastic Characteristics	QVX