


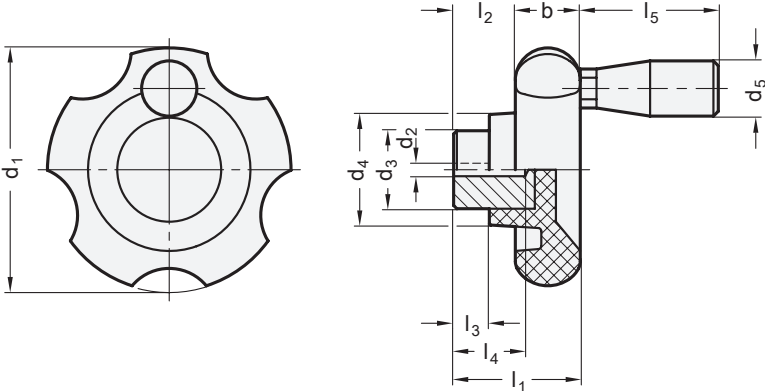

Universal table

Dimensions in: millimeters / inches										
d ₁	d ₂ Pilot hole	d ₃	d ₄	d ₅	b	l ₁	l ₂	l ₃	l ₄	l ₅
75 2.95	P 4	24 0.94	34 1.34	17 0.67	20 0.79	39 1.54	19 0.75	11 0.43	22 0.87	43 1.69
90 3.54	P 6	32 1.26	44 1.73	17 0.67	20 0.79	42 1.65	22 0.87	12 0.47	25 0.98	43 1.69

Specification

- Body**
Plastic, Phenolic (PF)
 - Operating temperature up to 266 °F (130 °C)
 - Black, shiny finish
- Hub bushing**
Steel, zinc plated
- Revolving handle**
Plastic, Phenolic (PF)
 - Black, shiny finish
 - Threaded spindleSteel, zinc plated

RoHS

On request

- Other modifications such as inch and metric blind bores, threads, etc.

Five-lobed control knobs VUM with revolving handle are ideally suited for light-medium duty adjusting or clamping applications.

see also...	Page
VUA Five-Lobed Control Knobs	QVX
VU Five-Lobed Control Knobs	QVX

Technical Information	
Keyways WN 6885 / DIN 6885-1	QVX
Plastic Characteristics	QVX