



3.1
3.2
3.3
3.4
3.5
3.6
3.7
3.8
3.9
3.10

Metric

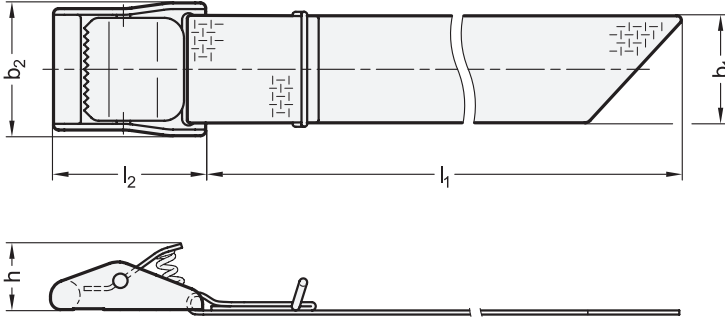

Application example

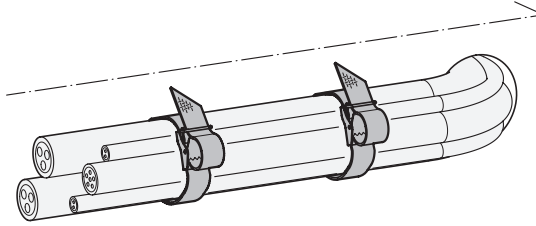

Metric table

Dimensions in: millimeters / inches

b ₁	l ₁					b ₂	h	l ₂	Load capacity	
	25	400	600	1000	1500				ST	NI
25 0.98	250 9.84	400 15.75	600 23.62	1000 39.37	1500 59.06	32 1.26	16 0.63	39 1.54	4000 N 899 lbf	6000 N 1349 lbf

Specification

Buckle

- Steel, black painted
- Stainless steel AISI 304

ST
NI

Strap

- Plastic
- Polypropylene (for ST)
- Polyester (for NI)
- Woven
- Black

● SW

RoHS

Lashing straps GN 1110 are used in various applications to tightly fasten and secure material.

see also...

GN 111.2 Retaining Cables

Page
QVX

Technical Information

Plastic Characteristics

QVX

Stainless Steel Characteristics

QVX

How to order

1	Width b ₁
2	Length l ₁
3	Material
4	Color

GN 1110-25-1000-ST-SW