




Type K

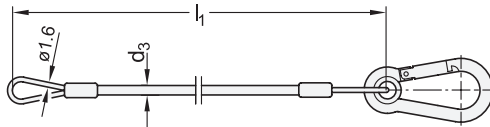

Type L

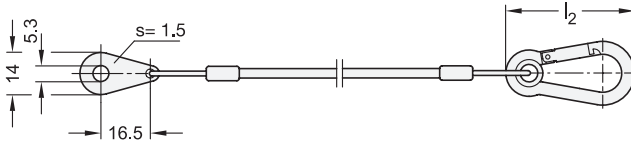

Type M

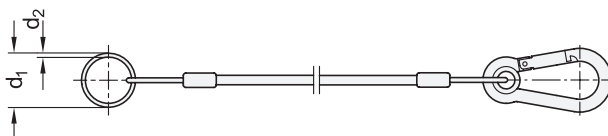

Metric



SS Stainless Steel

3 Type

- K** With carabiner and loop
- L** With carabiner and mounting tab
- M** With carabiner and key ring

Metric table

Dimensions in: millimeters / inches

1			2		5		Static load ≈	
l_1	d_1	l_2	d_2	d_3	Type K / L	Type M		
150 5.91	200 7.87	320 12.60	14 0.55	50 1.97	1 0.04	3 0.12	1200 N 270 lbf	50 N 11.24 lbf
150 5.91	200 7.87	320 12.60	18 0.71	50 1.97	1.3 0.05	3 0.12	1200 N 270 lbf	90 N 20.23 lbf
150 5.91	200 7.87	320 12.60	24 0.94	50 1.97	1.5 0.06	3 0.12	1200 N 270 lbf	100 N 22.48 lbf

2	d_1	Key rings (Type M) suitable for ball lock pins and rapid release pins with pin Ø							
		GN 113.1 GN 113.3 GN 113.4 GN 113.7 GN 113.8 GN 113.9 GN 113.10	GN 113.5 GN 113.6	GN 113.11 GN 113.12	GN 114.2 GN 114.3 GN 114.6	GN 124.1 GN 124.2	GN 124.3	GN 214.2 GN 214.3 GN 214.6	GN 314
14 0.55	5 / 6 / 8	all	5 / 6 / 8 / 10	all	all	8 / 10	6 / 8	-	
18 0.71	10 / 12 / 16 / 20 / 25	-	12 / 16	-	-	10 / 12	10 / 12 / 16	8 / 10 / 12	
24 0.94	-	-	20 / 25	-	-	-	-	16 / 20	

Specification

Retaining cable

- Stainless steel AISI 304
- Coated with plastic (PVC)
- Transparent



Carabiner / Round thimble

- Stainless steel AISI 316
- Plain finish

Mounting tab

- Stainless steel AISI 304

Key ring

- Stainless steel AISI 301
- Plain, tumbled finish

Press sleeves

- Aluminum
- Plain finish

RoHS

Technical Information

Stainless Steel Characteristics QVX

Accessory

- GN 111.3 Key Rings QVX
- GN 5299 Carabiners (Type C) QVX

Retaining cables GN 111.2 with carabiner are available in 3 different types and can therefore be used in a variety of applications, such as loss protection, or connecting and fastening cables.

The retaining cable is firmly connected on one side to a carabiner GN 5299. With type M, the key ring is loosely enclosed with the retaining cable.

The orientation of the cable loops, mounting tabs and carabiners may deviate from the drawing. The load values given in the table are non-binding guide values and rule out any liability.

see also...

- GN 111 Ball Chains QVX
- GN 111.4 Spiral Retaining Cables QVX

How to order (Type K and L)

GN 111.2-150-L-TR-50

- 1 Length l_1
- 3 Type
- 4 Color
- 5 Length l_2

How to order (Type M)

GN 111.2-320-24-M-TR-50

- 1 Length l_1
- 2 Diameter d_1
- 3 Type
- 4 Color
- 5 Length l_2