



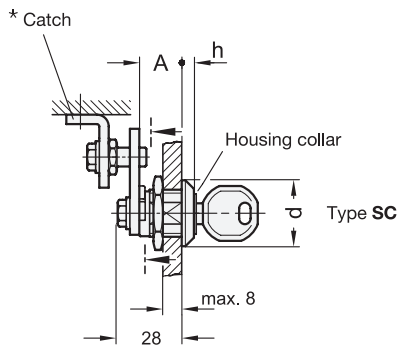

Metric

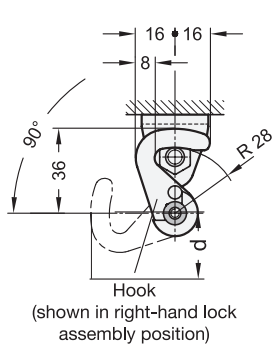

SS Stainless Steel

1 Type

- SC** With key (Keyed alike)
SCKN With wing knob (Keyed alike)
SCTN With T-handle (Keyed alike)


3 Hook version

H1 Pivoting radius R=28mm


5 Identification no.

- 1 Without latch bracket
2 With latch bracket

Type SCTN

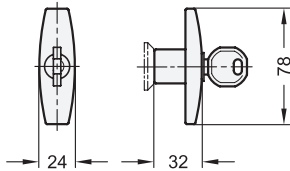

Type SCKN

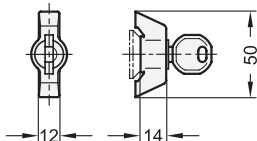

Metric table

Hook distance A	d		h
	Type SC	Type SCKN / SCTN	
18 0.71	28 1.10	32 1.26	6 0.24

* Dimensions of the latch bracket, see page XYZ

Specification

Cam lock housing

Stainless steel

N

- AISI 303 for type SC
- AISI 316 for type SCKN / SCTN

Operating elements for type SCKN / SCTN

Stainless steel AISI 316

Other parts

Stainless steel AISI 304

Key

Nickel silver with plastic handpiece

Protection class IP65

RoHS

On request

- Cam locks with other hook distance A
- Hook with other pivoting radius R

Cam locks with hook GN 115.8 with hook and latch bracket are mainly used for sliding doors and flaps. The locking action is in radial direction to the axis of rotation, resulting in a wide variety of different uses.

The latches are delivered with 2 keys and loosely enclosed hook. The key can be removed in both end positions.

Types with a standard lock allow every lock to be opened with the same key.

see also...

	Page
GN 115.8 Cam Locks with Hook (Zinc Die-Cast)	QVX
GN 115.8 Cam Latches with Hook (Stainless Steel, with Operating Elements)	QVX

Technical Information

Construction and Assembly Instructions	QVX
List of Cam Latch / Cam Lock Types	QVX
IP Protection Classes	QVX
Stainless Steel Characteristics	QVX

How to order

GN 115.8-SCTN-18-H1-N-1

- 1 Type
2 Hook distance A
3 Hook version
4 Material
5 Identification no.