


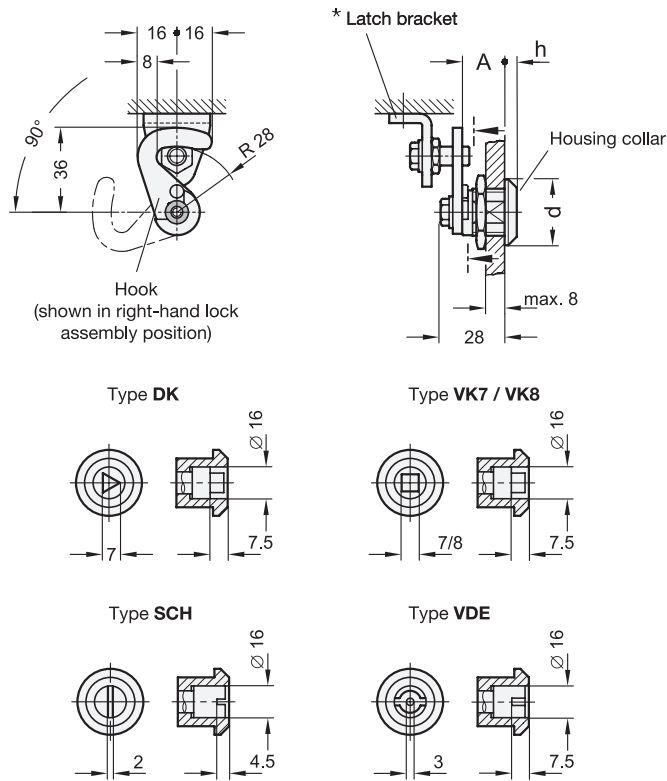

- SS

Stainless Steel
- 1

Type

DK With triangular spindle

VK7 With square spindle

VK8 With square spindle

SCH With slot

VDE With double bit
- 3

Hook version

H1 Pivoting radius R=28mm
- 5

Identification no.

1 Without latch bracket

2 With latch bracket

Metric table

Dimensions in: millimeters / inches		
Hook distance A	d	h
18 0.71	28 1.10	4 0.16

* Dimensions of the latch bracket, see page XYZ

Specification	
Cam latch housing	N
Stainless steel AISI 303	
Other parts	
Stainless steel AISI 304	
Protection class IP65	
RoHS	
On request	
• Cam latches with other hook distance A	
• Hook with other pivoting radius R	
Accessory	Page
GN 119.2 Socket Keys	QVX
GN 120 Protective Caps	QVX
GN 120.1 Finger Grip Opening Handles	QVX

Cam latches with hook GN 115.8 and latch bracket are mainly used for sliding doors and flaps. The latching action is in a radial direction to the axis of rotation, resulting in a wide variety of different uses. The latches GN 115.8 are supplied with loosely enclosed hook.

see also...	Page
GN 115.8 Cam Latches with Hook (Stainless Steel, with Operating Elements)	QVX
GN 115.8 Cam Latches with Hook (Zinc Die-Cast, Operation with Operating Elements)	QVX

Technical Information	
Construction and Assembly Instructions	QVX
List of Cam Latch / Cam Lock Types	QVX
IP Protection Classes	QVX
Stainless Steel Characteristics	QVX

How to order	
1	Type
2	Hook distance A
3	Hook version
4	Material
5	Identification no.
GN 115.8-VK8-18-H1-N-1	