



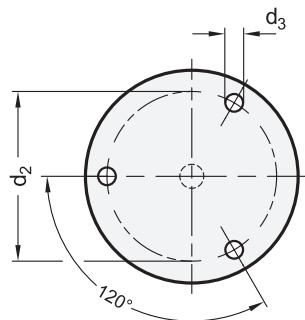

Metric

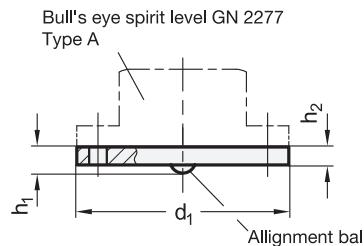

SS Stainless Steel

Metric table

2

Dimensions in: millimeters - *inches*

d ₁	d ₂	d ₃	h ₁	h ₂
20 0.79	17 0.67	1.8 0.07	3.2 0.13	1.2 0.05
25 0.98	21 0.83	2.2 0.09	3.2 0.13	1.2 0.05
30 1.18	24 0.94	3.2 0.13	3.2 0.13	1.2 0.05
40 1.57	34.5 1.36	3.2 0.13	3.2 0.13	1.2 0.05
50 1.97	43 1.69	3.2 0.13	3.2 0.13	1.2 0.05

Specification

1

- Stainless steel AISI 303

NI

- *Stainless Steel Characteristics* → page 2143

- RoHS compliant

Information

GN 2277.1 adjustment plates are used in combination with GN 2277 bull's eye spirit levels Type A.

The mounting bore holes offset by 120° allow the bull's eye spirit levels and the mounting plate to be aligned in relation to the mounting surface. An alignment ball at the bottom surface of the adjustment plate serves as a tilting point.

Specific tightening torques of the bolts are allowed to be achieved, so that the bubble is centrally located inside the marking ring once the horizontal alignment is reached.

see also...

- *General Information on Bull's Eye, Screw-On, and Cross Spirit Levels* → page 319
- *Bull's Eye Spirit Levels GN 2280 (Adjustable)* → www.jwwinco.com

How to order

1 2

GN 2277.1-NI-30

1 Material

2 Outside diameter d₁