


2 Type

K Compact design

3 Coding

X For fixed bearing guide rail

Mounting example

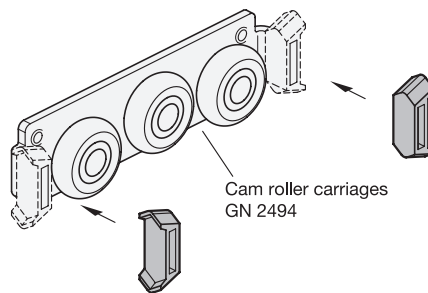

Metric table



Dimensions in: millimeters - inches

h₁ Rails GN 2492	b	h₂	l₁	l₂
30 1.18	8 0.31	10 0.39	8 0.31	3 0.12
45 1.77	12.5 0.49	20 0.79	11 0.43	4 0.16

Specification

- Wipers
Polyurethane (TPU)
Blue, FDA compliant
- Operating temperature -4 °F to 212 °F
(-20 °C to 100 °C)
- *Plastic Characteristics* → page QVX
- **RoHS compliant**

Information

GN 2498 wipers protect against dirt deposits in GN 2492 cam roller linear guide rails and GN 2496 cam rollers.

The wipers are provided as a replacement part for cam roller carriage GN 2494 to allow easy exchange in case of wear. Alternatively, they can be used on custom-built cam roller carriages. Only the rectangular cutout designated for fastening them to the cam roller carriage has to be taken into account.

The material can also be used in special environments that can be found, for example, in the pharmaceutical and food processing industries.

The wipers can be manually pushed onto the provided retaining tabs on the cam roller carriages and prepositioned. When inserting the carriage into the guide rail, check the position and adjust if necessary. The wipers will automatically assume proper alignment during operation.

see also...

- Assembly and Technical Instructions
(for Cam Roller Linear Guide Rails) → page QVX
- *Wipers GN 2428* → page QVX
- *Cam Roller Linear Guide Rail Systems GN 1490 (Steel / Stainless Steel)* → page QVX

How to order

GN 2498-30-K-X

- 1** Height h₁
- 2** Type
- 3** Coding

3.1
3.2
3.3
3.4
3.5
3.6
3.7
3.8
3.9
3.10