

4 Type

A Without accessory

Metric table

Dimensions in: millimeters - inches

| 1 s | | 2 Length l | | 3 n | d | h ₁ | k |
|-------------------|------------------|-------------------|------------------|------------|-----------|----------------|------------|
| Nominal dimension | Actual dimension | Nominal dimension | Actual dimension | | For screw | | |
| 30 1.18 | 30 1.18 | 30 1.18 | 30 1.18 | 6 0.24 | M 6 | 2.5 0.10 | - |
| 30 1.18 | 30 1.18 | 60 2.36 | 60 2.36 | 6 0.24 | M 6 | 3.5 0.14 | - |
| 40 1.57 | 40 1.57 | 40 1.57 | 40 1.57 | 8 0.31 | M 8 | 5 0.20 | - |
| 40 1.57 | 40 1.57 | 80 3.15 | 80 3.15 | 8 0.31 | M 8 | 5 0.20 | - |
| 80 3.15 | 74 2.91 | 80 3.15 | 76 2.99 | 8 0.31 | M 8 | 8 0.31 | 40 1.57 |

Specification

- Angle bracket
- Zinc die-cast
- Painted, white aluminum



ZW

- RoHS

Accessory

- T-nuts GN 50i → page QVX

Information

Angle brackets GN 30i fasten aluminum profiles to objects such as tables and panels or at right angles to each other. Machining of the profile is not necessary.

The connection can be freely positioned and slid along the slot. To fasten the angle brackets to a panel or transversely to an aluminum profile, the guide steps must be broken off.

see also...


- Aluminum Profiles GN 10i (Profile Type Light) → page QVX
- Aluminum Profiles GN 10i (Profile Type Heavy) → page QVX
- Aluminum Profiles GN 11i (with Partially Closed Slots) → page QVX

| How to order | |
|--------------|--------------|
| 1 | Width s |
| 2 | Length l |
| 3 | Slot width n |
| 4 | Type |
| 5 | Finish |


GN 30i-40 40 8-A-ZW

Assembly Options / Application Examples

Assembly of cover cap

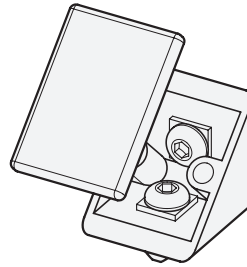

Use

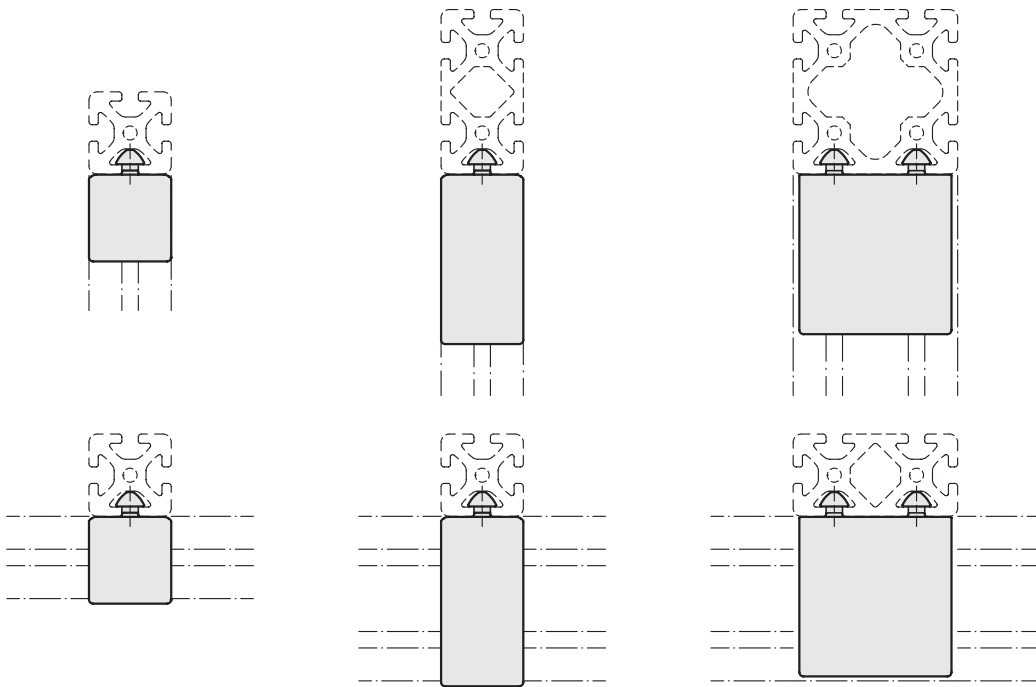

Application examples

