

**4 Type**

**C** With fastening set and cover cap

**Metric table**

<b>1</b>		<b>2</b>		<b>3</b>		Dimensions in: millimeters - inches		
s	Length l	n	d	h <sub>1</sub>	h <sub>2</sub> ≈	k		
Nominal dimension	Actual dimension	Nominal dimension	Actual dimension					
30 1.18	30 1.18	30 1.18	30 1.18	6 0.24	M 6	2.5 0.10	2 0.08	-
30 1.18	30 1.18	60 2.36	60 2.36	6 0.24	M 6	3.5 0.14	2 0.08	-
40 1.57	40 1.57	40 1.57	40 1.57	8 0.31	M 8	5 0.20	2 0.08	-
40 1.57	40 1.57	80 3.15	80 3.15	8 0.31	M 8	5 0.20	2 0.08	-
80 3.15	74 2.91	80 3.15	76 2.99	8 0.31	M 8	8 0.31	7 0.28	40 1.57

**Specification**

- Angle bracket  
Zinc die-cast  
Painted, white aluminum **ZW**
- Screws and T-nuts  
Steel  
Zinc plated, blue passivated finish **SZ**
- Cover cap  
Plastic (Polyamide PA)  
Black **S**
- *Plastic Characteristics* → page QVX
- RoHS

**Information**

Angle brackets GN 30i fasten aluminum profiles to objects such as tables and panels or at right angles to each other. Machining of the profile is not necessary.

The connection can be freely positioned and slid along the slot. To fasten the angle brackets to a panel or transversely to an aluminum profile, the guide steps must be broken off.

The cover caps ensure a visually appealing appearance and simplify cleaning.

see also...


- *Aluminum Profiles GN 10i (Profile Type Light)* → page QVX
- *Aluminum Profiles GN 10i (Profile Type Heavy)* → page QVX
- *Aluminum Profiles GN 11i (with Partially Closed Slots)* → page QVX

How to order	1 Width s
	2 Length l
	3 Slot width n
	4 Type
	5 Finish (Angle bracket)
	6 Material (Fastening set)
	7 Color of the cover cap


**GN 30i-80 80 8-C-ZW SZ S**

**Assembly Options / Application Examples**

Assembly of cover cap

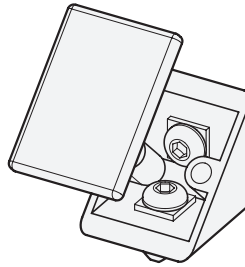

Use

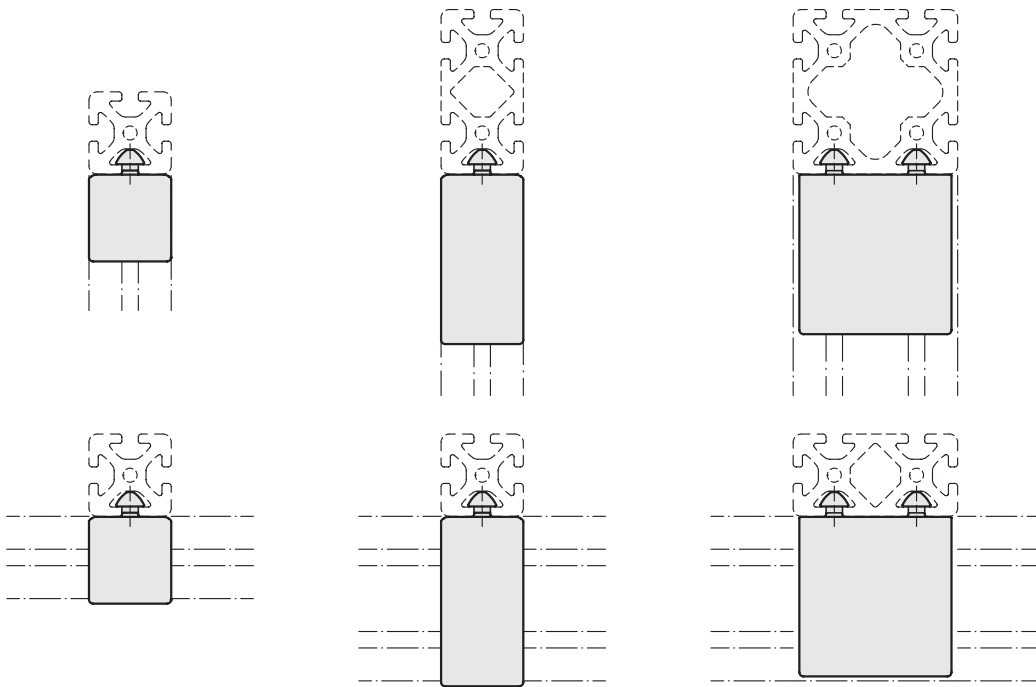

Application examples

