


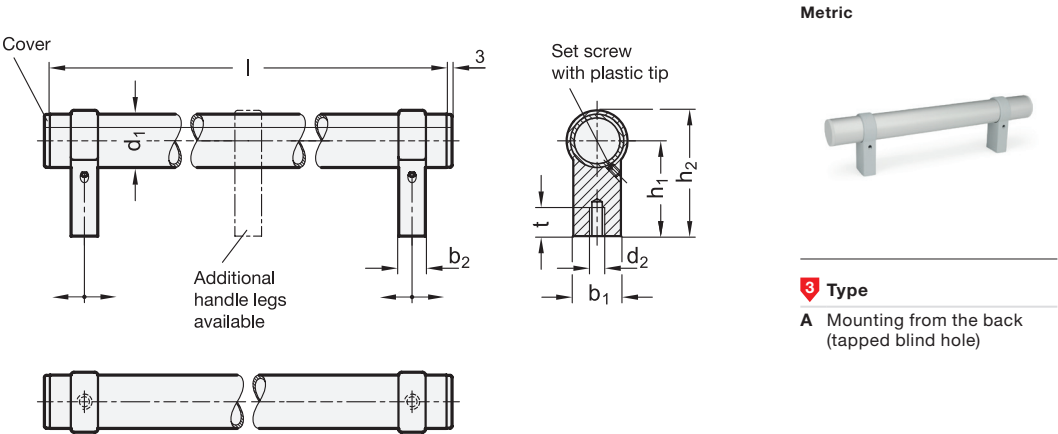

Metric table

1		2					Dimensions in: millimeters / inches					
d ₁	Length l						d ₂	b ₁	b ₂	h ₁	h ₂	t min.
28 1.10	242 9.53	292 11.50	392 15.43	492 19.37	592 23.31		M 8	25 0.98	14 0.55	50 1.97	66 2.60	15 0.59

Specification

4

Handle tube

Aluminum, wall thickness 1.5 mm

• Powder coated

Black, RAL 9005, textured finish

Handle legs black

• Anodized finish, natural color

Handle legs black

• Anodized finish, natural color

Handle legs silver

Handle legs

Zinc die-cast

Powder coated, textured finish

• Black, RAL 9005 for SW / ELS

• Silver, RAL 9006 for ESG

Cover

Plastic

• Black, matte finish for SW / ELS

• Light gray, matte finish for ELG

• SW

• ELS

• ELG

The spacing of the attachment holes of tubular handles GN 333.3 is adjustable. Additional handle legs can be added for very long tubular handles.

Further handle legs can be added for very long tubular handles. Individual handle legs for tubular handles Ø 28 (type A) are available under GN 333.9. Tubular handles GN 333.3 are supplied unassembled.

see also...	Page
GN 333.2 Tubular Handles (Movable Angled Handle Legs)	QVX
GN 333.1 Tubular Handles (Fixed Straight Handle Legs)	QVX
GN 930 Handle Tubes	QVX

Technical Information
Load Capacity Information

Accessory
GN 333.9 Straight Handle Legs

RoHS

On request

• Special tube lengths