


**Application examples**

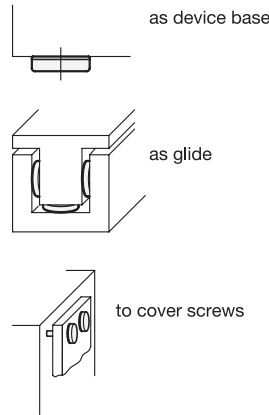

- 2 Type**
- KS** With cover cap, gliding
  - KR** With cover cap, non-slip

**Metric table**



Dimensions in: millimeters - inches

d <sub>1</sub>	d <sub>2</sub>	h <sub>1</sub>	h <sub>2</sub>	h <sub>3</sub>
16 0.63	3.2 0.13	5 0.20	1 0.04	3.7 0.15
20 0.79	4.3 0.17	5 0.20	1 0.04	3.7 0.15
25 0.98	4.3 0.17	5.7 0.22	1 0.04	4 0.16
32 1.26	5.3 0.21	6.7 0.26	1 0.04	5 0.20

**Specification**

- Disk  
Steel, zinc plated, blue passivated finish
- Cover cap  
Plastic
  - Type **KS**  
Technopolymer (Polyacetal POM)  
White, RAL 9001, natural color
  - Type **KR**  
Elastomer (TPE) ≈ 75 shore A  
Black
- *Plastic Characteristics* → page QVX
- *Elastomer Characteristics* → page QVX
- **RoHS compliant**

**On request**

- Colored cover caps

**Information**

The application examples above show the versatility of these GN 338 disks with cover cap. They are suitable for use as glides or non-slip feet on machinery. The type KS with gliding cover cap is ideally suited as a protective top or side cover for difficult to guide mechanical devices such as highly sensitive equipment. They can also be used as a shroud to cover mounting screws for a more appealing, finished look. The cover caps can be removed by inserting a screwdriver in the recess on the edge.

<p><b>How to order</b></p> <p><b>GN 338-25-KS</b></p>	<b>1</b> Outer diameter d <sub>1</sub>
	<b>2</b> Type

3.1  
3.2  
3.3  
3.4  
3.5  
3.6  
3.7  
3.8  
3.9  
3.10