


Application example

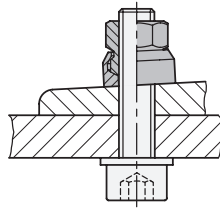

Metric table

Dimensions in: millimeters - inches

¹ d ₁	² d ₂ Thread	Length l ≈	A/F
17 0.67	M 8	14 0.55	13 0.51
21 0.83	M 10	17.5 0.69	16 0.63
24 0.94	M 12	21.5 0.85	18 0.71
30 1.18	M 16	28 1.10	24 0.94
36 1.42	M 20	35 1.38	30 1.18
44 1.73	M 24	42.5 1.67	36 1.42

Specification

- Steel
 - Property class 10
 - Blackened finish
- *Strength Values of Nuts* → page 2127
- [RoHS compliant](#)

Information

GN 347 swivel hex nuts are capable of clamping slanting, non-parallel surfaces at an incline of up to 3°. The nut is attached to prevent loss and ensure quick, reliable and efficient assembly.

How to order

GN 347-30-M16

- ¹ Diameter d₁
- ² Thread d₂

3.1
3.2
3.3
3.4
3.5
3.6
3.7
3.8
3.9
3.10

