


**4 Type**  
A Simply curved, 90°

Application example

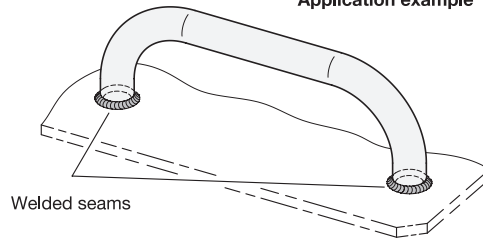

**Metric table**

Dimensions in: millimeters - inches

d	Length l ±1.5					h ±1.5	r	s
20 0.79	150 5.91	200 7.87	250 9.84	300 11.81	400 15.75	90 3.54	40 1.57	3 0.12
25 0.98	200 7.87	250 9.84	300 11.81	400 15.75	500 19.69	110 4.33	50 1.97	3 0.12
30 1.18	300 11.81	350 13.78	400 15.75	500 19.69	600 23.62	130 5.12	60 2.36	3 0.12

**Specification**

- Steel  
Plain finish, oiled
- RoHS compliant

**Information**

**ST** GN 426.3 cabinet “U” handles are manufactured from hollow seamless steel tubing.  
see also...  
• Cabinet “U” Handles GN 425.3 (Steel / Stainless Steel) → page 142

How to order	1 Material
<b>GN 426.3-ST-25-250-A</b>	2 Handle diameter d
	3 Length l
	4 Type

1.1  
1.2  
1.3  
1.4  
2.1  
2.2  
2.3  
2.4