


Metric



**Assembly instruction**

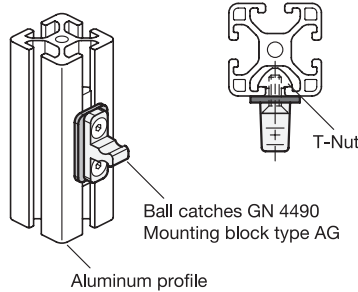

**3 Type**

**F Flat**

**Metric table**

Dimensions in: millimeters / inches

<b>l<sub>0</sub></b> Length of ball catch	<b>d</b>	<b>l<sub>1</sub></b>	<b>l<sub>2</sub></b>	<b>m</b>	<b>s</b>	For aluminum profiles with grid size
50 1.97	4.5 0.18	30 1.18	16 0.63	17 0.67	2 0.08	20 / 30 / 40 / 45
68 2.68	4.5 0.18	32.5 1.28	17 0.67	20 0.79	2 0.08	20 / 30 / 40 / 45
80 3.15	5.5 0.22	40 1.57	20 0.79	25 0.98	2 0.08	20 / 30 / 40 / 45

**Specification**

**Stainless steel** AISI 316  
Matte shot-blasted finish

**1** **4**  
**A4** **GS**

RoHS

Mounting plates GN 4490.2 enlarge the contact surface of the mounting blocks of ball catches GN 4490. This allows mounting blocks to be securely attached to aluminum profiles regardless of the slot width.

see also...

	Page
<b>GN 4490</b> Ball Catches	QVX
<b>GN 4490.1</b> Mounting Plates (for Ball Housings)	QVX

**Technical Information**

Stainless Steel Characteristics	QVX
---------------------------------	-----

**Accessory**

<b>GN 50b</b> T-Nuts	QVX
<b>GN 50i</b> T-Nuts	QVX
<b>GN 51b</b> T-Slot Nuts	QVX

**How to order**

<b>1</b> Material
<b>2</b> Length <b>l<sub>0</sub></b>
<b>3</b> Type
<b>4</b> Finish

**GN 4490.2-A4-50-F-GS**

3.1  
3.2  
3.3  
3.4  
3.5  
3.6  
3.7  
3.8  
3.9  
3.10