



Metric

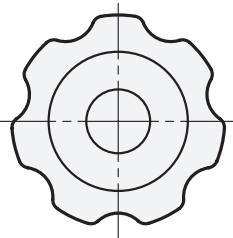

elesa
Original design GFL-B / GFL-p

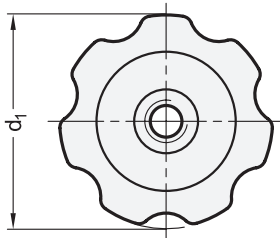

Metric table

Dimensions in: millimeters / inches							
1 d ₁	2 d ₂	3 Length l		d ₃	d ₄	h	k
40 1.57	M 6	20 0.79	28 1.10	12 0.47	25 0.98	10 0.39	8.5 0.33
40 1.57	M 8	20 0.79	28 1.10	12 0.47	25 0.98	10 0.39	8.5 0.33
40 1.57	M 10	28 1.10	38 1.50	13 0.51	25 0.98	10 0.39	8.5 0.33
50 1.97	M 8	20 0.79	28 1.10	12 0.47	25 0.98	10 0.39	8.5 0.33
50 1.97	M 10	28 1.10	38 1.50	13 0.51	25 0.98	10 0.39	8.5 0.33

Specification

Knob

- Plastic, Polyamide (PA)
- Glass fiber reinforced
- Operating temperature
-22 °F to +212 °F (-30 °C to +100 °C)
- Black, matte finish

● SW

Threaded bushing
Brass

Threaded stud
Steel

RoHS

Lobed thumb nuts / screws EN 567 can be used to lock and secure by utilizing two thumb nuts on a threaded shaft. They also require minimal space due to their thin profile.

The ergonomic shape makes them easy to grip during use.

see also...

	Page
DIN 467 Knurled Nuts	QVX
DIN 653 Knurled Thumb Screws	QVX

Technical Information

Plastic Characteristics	QVX
-------------------------	-----

How to order (Threaded stud)	
1	Handle diameter d ₁
2	Thread d ₂
3	Length l
4	Color
EN 567-50-M10-28-SW	

How to order (Threaded bushing)	
1	Handle diameter d ₁
2	Thread d ₂
3	Color
EN 567-40-M8-SW	