



Metric

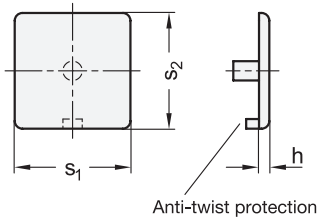

Application example

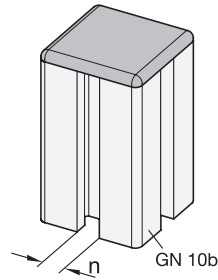

4 Type

P Press-on type

Metric table

1 s ₁	2 s ₂	3 n	h ≈	Grid size
30 1.18	30 1.18	8 0.31	3 0.12	30 1.18
30 1.18	60 2.36	8 0.31	3 0.12	30 1.18
40 1.57	40 1.57	10 0.39	4 0.16	40 1.57
40 1.57	80 3.15	10 0.39	4 0.16	40 1.57
45 1.77	45 1.77	10 0.39	4 0.16	45 1.77
45 1.77	60 2.36	10 0.39	4 0.16	45 1.77
45 1.77	90 3.54	10 0.39	4 0.16	45 1.77
80 3.15	80 3.15	10 0.39	4 0.16	40 1.57
90* 3.54	90 3.54	10 0.39	4 0.16	45 1.77

* Only compatible with profile type L

Specification

Plastic, Polyamide (PA)
Black

● **KS**

RoHS

Cover caps GN 60b make a visually appealing closure for the end faces of aluminum profiles, protecting against injuries from sharp cut edges and preventing the ingress of dust and dirt. They can be fitted without machining the profile.

see also...

	Page
GN 10b Aluminum Profiles (Profile Type Light)	QVX
GN 10b Aluminum Profiles (Profile Type Heavy)	QVX

Technical Information

Plastic Characteristics	QVX
-------------------------	-----

How to order

1 Width s ₁
2 Width s ₂
3 Slot width n
4 Type
5 Color

GN 60b-459010-P-KS

3.1
3.2
3.3
3.4
3.5
3.6
3.7
3.8
3.9
3.10

