


Application example

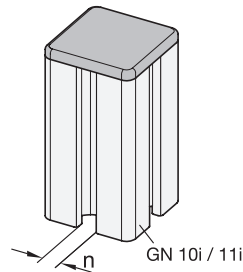

4 Type

P Press-on type

Metric table

1 s ₁	2 s ₂	3 n	h ≈	Grid size
30 1.18	30 1.18	6 0.24	3 0.12	30 1.18
30 1.18	60 2.36	6 0.24	3 0.12	30 1.18
40 1.57	16 0.63	8 0.31	4 0.16	40 1.57
40 1.57	40 1.57	8 0.31	4 0.16	40 1.57
40 1.57	80 3.15	8 0.31	4 0.16	40 1.57
60 2.36	60 2.36	6 0.24	3 0.12	30 1.18
80 3.15	80 3.15	8 0.31	4 0.16	40 1.57

Dimensions in: millimeters - inches

Specification

- Plastic (Polyamide PA)
Black
- Plastic Characteristics → page QVX
- RoHS



Information

Cover caps GN 60i make a visually appealing closure for the end faces of aluminum profiles, protecting against injuries from sharp cut edges and preventing the ingress of dust and dirt.

They can be fitted without machining the profile.

see also...

- Aluminum Profiles GN 10i (Profile Type Light) → page QVX
- Aluminum Profiles GN 10i (Profile Type Heavy) → page QVX
- Aluminum Profiles GN 11i (with Partially Closed Slots) → page QVX

How to order	
1	Width s ₁
2	Width s ₂
3	Slot width n
4	Type
5	Color

GN 60i-40808-P-KS