


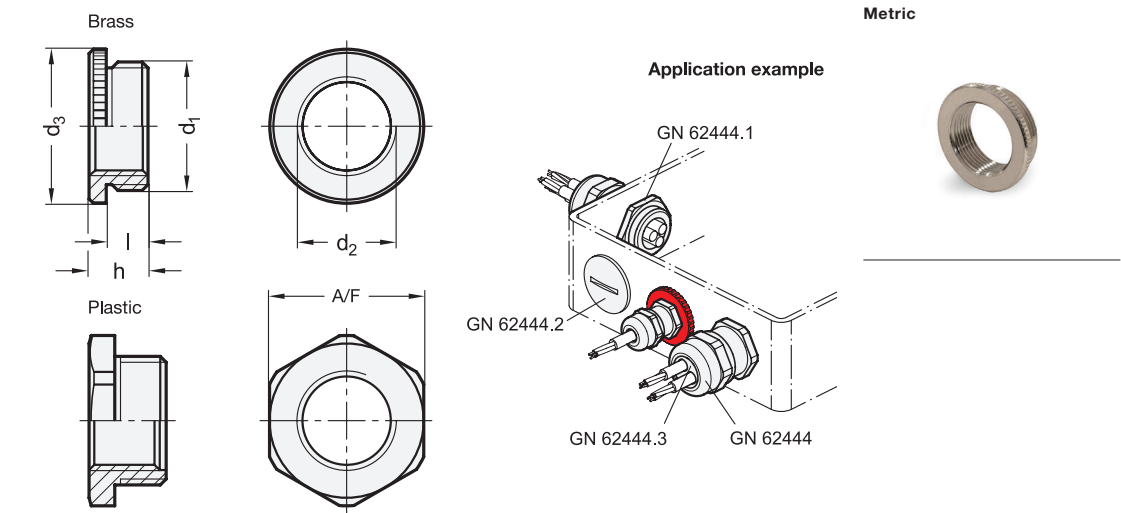

Metric table

1

Dimensions in: millimeters / inches

Size	d ₁	d ₂	d ₃	h		Length l		A/F
				MS	KLG	MS	KLG	
M 16-M 12	M 16 x 1.5	M 12 x 1.5	20 0.79	8 0.31	12 0.47	6 0.24	8 0.31	24 0.94
M 20-M 16	M 20 x 1.5	M 16 x 1.5	24 0.94	9 0.35	12 0.47	6.5 0.26	8 0.31	24 0.94
M 25-M 20	M 25 x 1.5	M 20 x 1.5	30 1.18	10 0.39	14 0.55	7 0.28	8 0.31	32 1.26
M 32-M 25	M 32 x 1.5	M 25 x 1.5	37 1.46	11.5 0.45	16 0.63	8 0.31	10 0.39	36 1.42
M 40-M 32	M 40 x 1.5	M 32 x 1.5	43 1.69	11.5 0.45	19 0.75	8 0.31	12 0.47	46 1.81
M 50-M 40	M 50 x 1.5	M 40 x 1.5	56 2.20	14 0.55	21 0.83	10 0.39	14 0.55	55 2.17
M 63-M 50	M 63 x 1.5	M 50 x 1.5	66 2.60	14 0.55	22 0.87	10 0.39	15 0.59	65 2.56

Specification

2

Brass

MS

Nickel-plated

Plastic, polyamide (PA)

KLK

• Glass fiber reinforced

• Operating temperature
-22 °F to +212 °F (-30 °C to +100 °C)

• Gray, RAL 7035

RoHS

Reducers GN 62444.4 enable a transition from a larger to a smaller internal thread, allowing the use of smaller cord grips than the housing was designed for. In combination with a mounting nut, fastening in a through hole is also possible.

see also...

GN 62444 Cord Grips (Metric Thread) QVX

GN 62444.1 Thin Hex Nuts (Metric Thread) QVX

GN 62444.2 Threaded Plugs (Metric Thread) QVX

GN 62444.3 Multiple Sealing Inserts QVX

Technical Information

Plastic Characteristics QVX

Accessory

GN 62444.1 Thin Hex Nuts QVX

www.jwwinco.com | 1-800-877-8351

⚠ WARNING: Cancer and Reproductive Harm — www.P65Warnings.ca.gov

1