


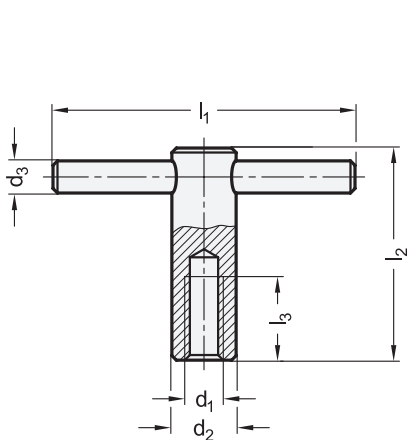

Metric table

1

d ₁	d ₂	d ₃	l ₁	l ₂	l ₃ min.
M 10	18 0.71	8 0.31	80 3.15	60 2.36	20 0.79
M 12	20 0.79	10 0.39	100 3.94	70 2.76	25 0.98
M 16	24 0.94	12 0.47	120 4.72	85 3.35	35 1.38
M 20	30 1.18	16 0.63	140 5.51	95 3.74	40 1.57

Dimensions in: millimeters / inches

Specification

Steel	Tommy nuts DIN 6305 are an ideal choice over a plastic T-knob where a higher clamping torque is required.
• Property class 5	see also...
• Blackened finish	
RoHS	
	Page
	DIN 6307 Tommy Nuts (with Movable Bar) QVX
	GN 6305.1 Quick Release Toggle Nuts (Steel) QVX
	Technical Information
	Strength Values of Nuts QVX