


Metric



**elesa**  
Original design ADT

Assembly examples

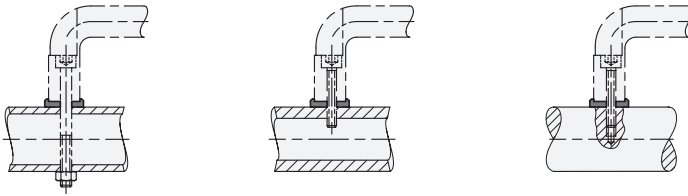

Metric table

<b>1</b> $d_1$			<b>2</b> $a$	<b>3</b> $b$	$d_2$	$h_1$	$h_2$	$h_3$	$l_1$	$l_2$	$s$	For cabinet U-handles
Nominal dimension	min.	max.										
30	28.6	32	14	23	5	1.5	11	45	5.5	1.5	1.5	EN 725.1-86
1.18	1.13	1.26	0.55	0.91	0.20	0.06	0.43	1.77	0.22	0.06	0.06	
30	28.6	32	16	25	6	1.5	13	51	6.5	1.5	1.5	EN 725.1-117
1.18	1.13	1.26	0.63	0.98	0.24	0.06	0.51	2.01	0.26	0.06	0.06	

Dimensions in: millimeters / inches

Specification

- Plastic, Polyamide (PA)
- Glass fiber reinforced
- Operating temperature -22 °F to +266 °F (-30 °C to +130 °C)
- Black, matte finish

RoHS

Mounting adapters EN 725.2 allow you to install cabinet U-handles EN 725.1 on tubes and rods with diameters ranging from 28.6 to 32 mm.

see also... **EN 725.1 Cabinet U-Handles (Polypropylene)** Page QVX

Technical Information

Plastic Characteristics QVX

How to order

**EN 725.2-30-14-23**

- 1** Diameter  $d_1$
- 2** Width  $a$
- 3** Length  $b$

1.1 1.2 1.3 1.4 2.1 2.2 2.3 2.4

