


Accessory for Knee Lever Modules


Weldable, for GN 810.12 and GN 810.13

Handles

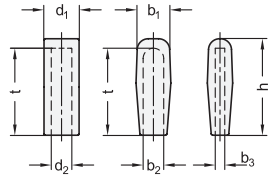


Module size	b ₁	d ₁	b ₂	d ₂	b ₃	h	t	Part number
220	22 <i>0.87</i>	-	13 <i>0.51</i>	-	5 <i>0.20</i>	60 <i>2.36</i>	55 <i>2.17</i>	GN 810.15-220
440	31 <i>1.22</i>	-	20 <i>0.79</i>	-	8 <i>0.31</i>	86 <i>3.39</i>	77 <i>3.03</i>	GN 810.15-440
850	-	30 <i>1.18</i>	-	22 <i>0.87</i>	-	119 <i>4.69</i>	112 <i>4.41</i>	GN 810.15-850
1540	-	34 <i>1.34</i>	-	25 <i>0.98</i>	-	119 <i>4.69</i>	112 <i>4.41</i>	GN 810.15-1540


Arm levers

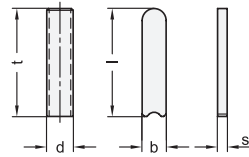

Module size	b	d	Length l	s	Part number
220	13 <i>0.51</i>	-	60 <i>2.36</i>	5 <i>0.20</i>	GN 810.16-220
440	20 <i>0.79</i>	-	90 <i>3.39</i>	8 <i>0.31</i>	GN 810.16-440
850	-	22 <i>0.87</i>	122 <i>4.80</i>	-	GN 810.16-850
1540	-	25 <i>0.98</i>	138 <i>5.43</i>	-	GN 810.16-1540

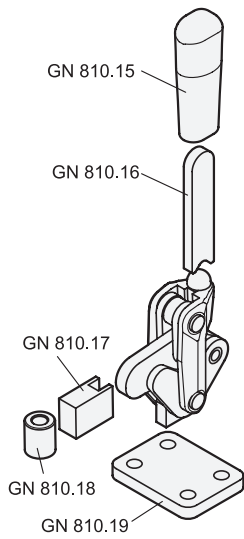


Clamping arm extenders

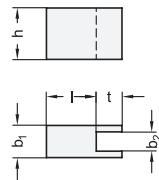


Module size	b ₁	b ₂	h	Length l	t	Part number
220	10 <i>0.39</i>	6 <i>0.24</i>	16 <i>0.63</i>	15.5 <i>0.61</i>	6.5 <i>0.26</i>	GN 810.17-220
440	15 <i>0.59</i>	10 <i>0.39</i>	24 <i>0.94</i>	16 <i>0.63</i>	8 <i>0.31</i>	GN 810.17-440
850	20 <i>0.79</i>	12 <i>0.47</i>	30 <i>1.18</i>	22.1 <i>0.87</i>	15 <i>0.59</i>	GN 810.17-850
1540	25 <i>0.98</i>	16.2 <i>0.64</i>	35 <i>1.38</i>	23.5 <i>0.93</i>	15 <i>0.59</i>	GN 810.17-1540

 Bushings



Module size	d ₁	d ₂	Length l	Part number
220	13 <i>0.51</i>	6.5 <i>0.26</i>	16 <i>0.63</i>	GN 810.18-220
440	20 <i>0.79</i>	10.5 <i>0.41</i>	24 <i>0.94</i>	GN 810.18-440
850	24 <i>0.94</i>	12.5 <i>0.49</i>	30 <i>1.18</i>	GN 810.18-850
1540	32 <i>1.26</i>	16.5 <i>0.65</i>	35 <i>1.38</i>	GN 810.18-1540

Base plates

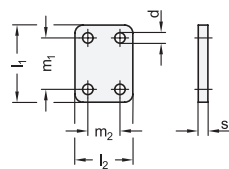

Module size	d	l ₁	l ₂	m ₁	m ₂	s	Part number
220	6.5 <i>0.26</i>	48 <i>1.89</i>	36 <i>1.42</i>	32 <i>1.26</i>	20 <i>0.79</i>	6 <i>0.24</i>	GN 810.19-220
440	8.5 <i>0.33</i>	65 <i>2.56</i>	54 <i>2.13</i>	45 <i>1.77</i>	30 <i>1.18</i>	8 <i>0.31</i>	GN 810.19-440
850	10.5 <i>0.41</i>	75 <i>2.95</i>	75 <i>2.95</i>	55 <i>2.17</i>	55 <i>2.17</i>	10 <i>0.39</i>	GN 810.19-850
1540	12.5 <i>0.49</i>	100 <i>3.94</i>	90 <i>3.54</i>	65 <i>2.56</i>	65 <i>2.56</i>	10 <i>0.39</i>	GN 810.19-1540