



SS Stainless Steel

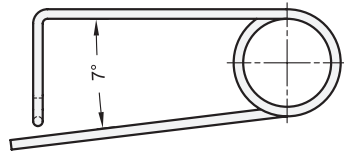

**Application example**

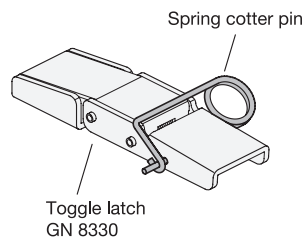

**Metric table**



Dimensions in: millimeters - inches

d <sub>1</sub>	d <sub>2</sub>	l <sub>1</sub> +1	l <sub>2</sub> ±1	For toggle latches GN 8330
9 0.35	1.2 0.05	20 0.787	3.6 0.142	15 0.59
11 0.43	1.2 0.05	25 0.984	3.6 0.142	20 0.79
13 0.51	2 0.08	34 1.339	6 0.236	29 1.14
15 0.59	2 0.08	45 1.772	6 0.236	40 1.57

**Specification**

- Stainless steel AISI 304
- *Stainless Steel Characteristics* → page QVX
- RoHS

**Information**

Spring cotter pins GN 8330.1 are used as accessories for toggle latches GN 8330 to secure them against unintended opening.

They are also used for the axial fixing of bolts and axes and to prevent twisting, e.g. for crown nuts DIN 935.

**see also...**

- *Toggle Latches GN 8330 (Steel, Zinc Plated)* → page XYZ
- *Toggle Latches GN 8330 (Stainless Steel)* → page XYZ

**How to order**

**GN8330.1-11**



1 Diameter d<sub>1</sub>