 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
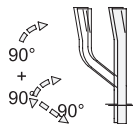
 
 
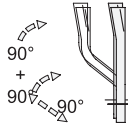
 
 
 
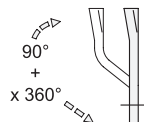
 
 
 
 
 
 
 
 
 
 
 
 
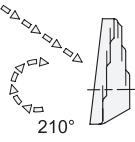
 
 
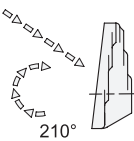
 
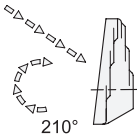
 
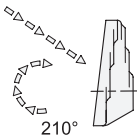
 
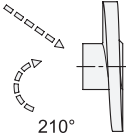
 


Series	Latch arm type	Housing type	Operating options
GN 115 Page 1260 / 1262 / 1263 Cam Latches Zinc die-cast, chrome plated or black powder coated locating ring, steel latch arm 			
GN 115.9 Page 1264 / 1265 Safety Cam Latches Zinc die-cast, black powder coated locating ring, steel latch arm 			
GN 115 Page 1266 / 1267 / 1268 Cam Latches Stainless steel SS Stainless Steel 			
GN 115 Page XYZ Cam Latches Stainless steel (AISI 304 / AISI 316) Protection class IP 69k SS Stainless Steel 			
GN 515 Page XYZ / XYZ Cam Latches with extended housing Zinc die-cast, Housing collar black powder coated, Latch arm steel 			
GN 515 Page XYZ / XYZ Cam Latches with extended housing Stainless steel SS Stainless Steel 			

Series	Latch arm type	Housing type	Operating options
GN 1150 Page XYZ / XYZ Cam Latches Stainless steel, Operating / latch arm side in Hygienic Design SS Stainless Steel 316L FDA	 		
GN 115.1 Page 1270 Cam Latches / Cam Locks Zinc die-cast, chrome plated finish, steel latch arm	 		
GN 115.6 Page 1272 Cam Latches Stainless steel SS Stainless Steel	 		
EN 115.3 www.jwwinco.com Cam Latches Technopolymer plastic	 		
EN 115.5 www.jwwinco.com Cam Latches Technopolymer plastic, snap-fit mounting	 		
EN 217 www.jwwinco.com Cam Latches / Cam Locks Technopolymer plastic steel latch arm	 		

Series	Latch arm type	Housing type	Operating options
EN 623.1 www.jwwinco.com Cam Latches / Cam Locks Technopolymer plastic, steel latch arm    			
GN 115.7 Page 1274 Cam Latches with Cabinet “U” Handle Zinc die-cast, steel latch arm    			
GN 115.10 Page 1276 / 1278 Cam Latches with Gripping Tray Zinc die-cast / plastic, steel latch arm, clamp-mounted    			
EN 731.2 Page 1280 Cam Locks with Gripping Tray Technopolymer plastic, steel latch arm, snap-fit mounting     SS Stainless Steel			
EN 731.5 Page XYZ Cam Latches with Gripping Tray Technopolymer plastic, stainless steel latch arm, snap-fit mounting     SS Stainless Steel			
GN 116.1 Page 1282 Spring Loaded Cam Latches Zinc die-cast, black powder coated locating ring, steel latch arm    			

Series		Latch arm type	Housing type	Operating options	
GN 516 Page 1284 Compression Cam Latches Zinc die-cast, black powder coated locating ring, steel latch arm					
GN 516.5 Page 1286 Compression Cam Latches Stainless steel					
GN 516.1 Page 1287 Compression Cam Latches Zinc die-cast, black powder coated locating ring, adjustable latch arm					
EN 5630 Page 1288 Lift and Turn Compression Latches Technopolymer plastic, zinc die-cast					
GN 117 Page 1290 Door Cam Latches Steel					
GN 119 Page 1292 Door Cam Latches Zinc die-cast, chrome plated finish, steel latch arm					

Series	Latch arm type	Housing type	Operating options
GN 119 Page 1294 Door Cam Latches Stainless steel SS Stainless Steel 	 210°		
EN 118 www.jwwinco.com Door Cam Latches Stintered steel latch arm 	 210°		
GN 119.3 Page 1296 Door Cam Latches with Cabinet “U” Handle Zinc die-cast, black or silver powder coated, steel latch arm 	 210°		
GN 115.8 Page 1298 / 1300 / 1301 Cam Latches / Cam Locks with Hook Zinc die-cast, chrome plated or black powder coated locating ring, zinc plated steel hook 	 90°		